


# 150M Standard U-Bolt – 150M0050EG



- Pipe support for general piping applications
- Comes complete with 4 nuts (2 installed on each end)
- Conforms with Federal Specification WW-H-171 (Type 24), Manufacturers Standardization Society ANSI®/MSS-SP-58 (Type 24)

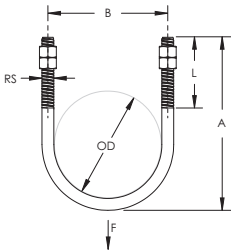

Part Number	150M0050EG
Material	Steel
Finish	Electrogalvanized
Pipe Size	1/2"
Outer Diameter (OD)	0.84"
Rod Size (RS)	1/4"
Screw Length (L)	2 3/8"
A	3 1/2"
B	1 1/16"
Static Load (F)	435 lb
Standard Packaging Quantity	100 pc
UPC	78285660150
EAN-13	8711893088748

ANSI is a registered trademark of American National Standards Institute.

#### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.erico.com](http://www.erico.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

© 2020 nVent All rights reserved

nVent, nVent CADDY, nVent ERICO, nVent ERIFLEX and nVent LENTON are owned by nVent or its global affiliates.

All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without prior notice.

