 



# SK Single Piece Strut Clamp for Conduit – SK405I



- One piece break apart strut clamp for EMT and Rigid conduit
- Includes thread impression and captured screw

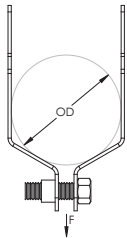

|                             |                   |
|-----------------------------|-------------------|
| Part Number                 | SK405I            |
| Material                    | Steel             |
| Finish                      | Electrogalvanized |
| EMT Conduit Size            | 2 1/2"            |
| Rigid Conduit/Pipe Size     | 2 1/2"            |
| Outer Diameter (OD)         | 2.88"             |
| Width (W)                   | 1 1/4"            |
| Static Load (F)             | 350 lb            |
| Certifications              | cULus             |
| Standard Packaging Quantity | 50 pc             |
| UPC                         | 78285625342       |
| EAN-13                      | 8711893018783     |

UL, UR, cUL, cUR, cULus and cURus are registered certification marks of UL LLC.

#### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.erico.com](http://www.erico.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

© 2020 nVent All rights reserved

nVent, nVent CADDY, nVent ERICO, nVent ERIFLEX and nVent LENTON are owned by nVent or its global affiliates.

All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without prior notice.

