



USC Universal Strut Clamp for Pipe/Conduit – USC028EG

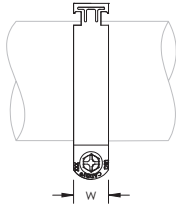

- Consists of two clamps, nut and bolt
- Fits into open side of strut channel
- Conforms with Manufacturers Standardization Society (MSS) SP-58 (Type 59)

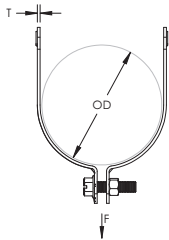

Part Number	USC028EG
Material	Steel
Finish	Electrogalvanized
Outer Diameter (OD)	1.10" – 1.14"
Width (W)	1 1/4"
Thickness (T)	16 GA
Static Load (F)	450 lb
Standard Packaging Quantity	100 pc
UPC	78285680363
EAN-13	8711893140408

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.erico.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

© 2020 nVent All rights reserved

nVent, nVent CADDY, nVent ERICO, nVent ERIFLEX and nVent LENTON are owned by nVent or its global affiliates.

All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without prior notice.

