


# USC Universal Strut Clamp for Copper Tube – USC129BR



- Consists of two clamps, nut and bolt
- Fits into open side of strut channel
- FM® Specification Tested (from 1/2" to 4" of Copper Tube Size)

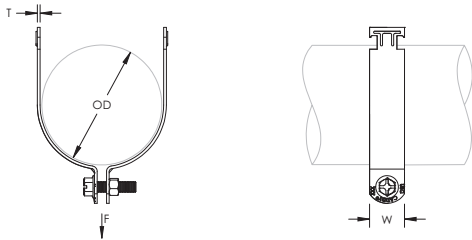

Part Number	USC129BR
Material	Steel
Finish	Polyester
Outer Diameter (OD)	5.00" – 5.13"
Copper Tube Size	5"
Width (W)	1 1/4"
Thickness (T)	12 GA
Static Load (F)	850 lb
Standard Packaging Quantity	25 pc
UPC	78285680469

FM is a registered certification mark of FM Approvals LLC, LTD.

#### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.erico.com](http://www.erico.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

© 2020 nVent All rights reserved

nVent, nVent CADDY, nVent ERICO, nVent ERIFLEX and nVent LENTON are owned by nVent or its global affiliates.

All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without prior notice.

