



Cable Clamp – LPC858

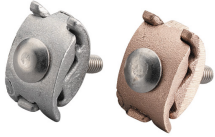

- Clamps to flat metal objects such as I-beams, angle irons and channel irons
- Can be used as a parallel conductor clamp
- Positive bolt tension draws tight on steel member
- Listed to UL® 96

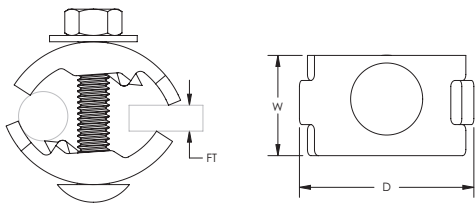

Part Number	LPC858
Conductor Size, UL	Class 1 - Class 2 (4/0 Max) Secondary
Material	Brass
Flange Thickness (FT)	1/2" Max
Depth (D)	1.66"
Width (W)	0.89"
Unit Weight	0.24 lb
Certifications	UL
Standard Packaging Quantity	1 pc
UPC	78285643189

Flange thickness will impact the maximum cable holding capability.

UL, UR, cUL, cUR, cULus and cURus are registered certification marks of UL LLC.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.erico.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

© 2020 nVent All rights reserved

nVent, nVent CADDY, nVent ERICO, nVent ERIFLEX and nVent LENTON are owned by nVent or its global affiliates.

All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without prior notice.