

# Rittal – The System.

Faster – better – everywhere.

## Gland plate module, one-piece, with brush strip for VX IT – VX 5301.333

Date : Dec 17, 2020

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# Gland plate module, one-piece, with brush strip for VX IT – VX 5301.333

created: 17.12.2020 on [www.rittal.com/com-en](http://www.rittal.com/com-en)

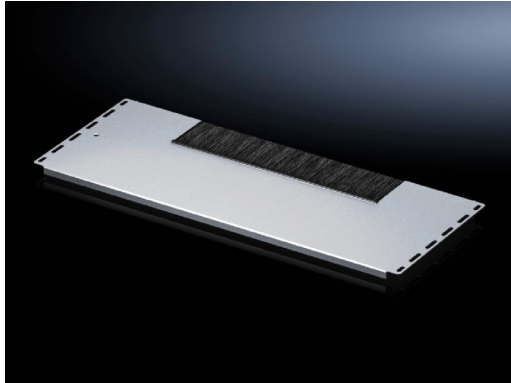

## Product description

<b>Design:</b>	one-piece, with brush strip
<b>Description:</b>	For targeted cable entry from below.
<b>Material:</b>	Module plate: Sheet steel Brush strip: Plastic, UL 94 HB, halogen-free
<b>Surface finish:</b>	Module plate: Zinc-plated
<b>Assembly instruction:</b>	Several gland module plates must be combined to seal the base completely in the VX IT The gland plate module may be combined in exchange with other base modules with a depth of 237.5 mm.
<b>Supply includes:</b>	Assembly parts
<b>Note:</b>	Gland plate modules with brush strip not suitable for applications with a protection category to IEC 60 529

## Product features

<b>To fit:</b>	Enclosure type: VX IT Width: = 800 mm
<b>Dimensions:</b>	Depth: 237.5 mm
<b>Packs of:</b>	1 pc(s).

<b>Copper weight (kg per piece):</b>	0
<b>EAN:</b>	4028177950856
<b>Customs tariff number:</b>	94039010
<b>ETIM 7.0:</b>	EC002620
<b>ETIM 6.0:</b>	EC002620
<b>eCl@ss 8.0/8.1:</b>	27189261
<b>eCl@ss 6.0/6.1:</b>	27182003
<b>Product description:</b>	VX IT gland plate module with brush strip, for width 800 mm, W x D 600 x 237.5 mm, one-piece, sheet steel