

# Rittal – The System.

Faster – better – everywhere.

► **Network/server rack  
VX IT with glazed  
door, IP 55, with 482.6  
mm (19") mounting  
angles, standard – VX  
5329.131**

Date : Dec 17, 2020

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# Network/server rack VX IT with glazed door, IP 55, with 482.6 mm (19") mounting angles, standard – VX 5329.131

created: 17.12.2020 on [www.rittal.com/com-en](http://www.rittal.com/com-en)

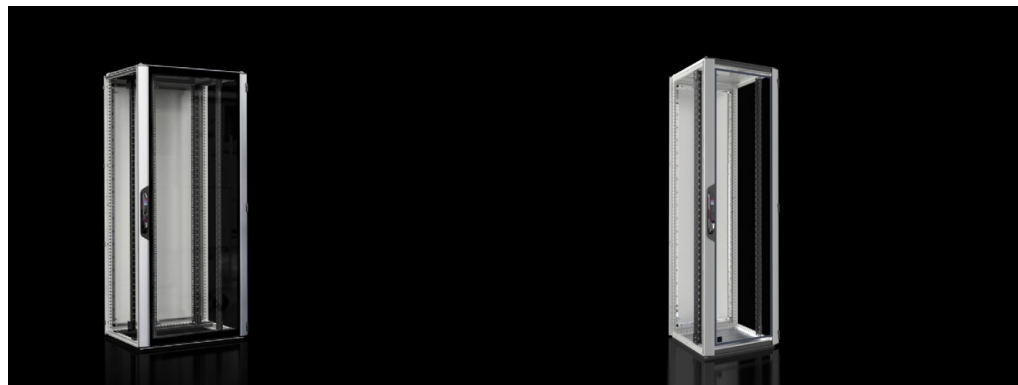

## Product description

<b>Material:</b>	Sheet steel Aluminium Glazed door: Single-pane safety glass, 3 mm
<b>Surface finish:</b>	Enclosure frame: Dipcoat-primed Interior installation: Spray-finished Rear door and roof: Dipcoat-primed, powder-coated Front door: Aluminium, anodised/spray-finished
<b>Colour:</b>	Enclosure frame, rear door and roof: RAL 7035 Front door: Vertical sections, silver coloured and horizontal sections, RAL 9005 Interior installation: RAL 9005 Handle and hinges: RAL 9005
<b>Protection category IP to IEC 60 529:</b>	IP 55 only in conjunction with baying seal or screw-fastened side panels
<b>Supply includes:</b>	VX enclosure frame with doors and roof plate Glazed aluminium door at the front, 180° hinges Sheet steel rear door, solid, one-piece, 130° hinges Lock front and rear: Comfort handle for profile half-cylinders and security lock 3524 E Mounting angles, 482.6 mm (19") Roof plate, one-piece, solid Base tray with gland plate, multi-piece, solid Baying seal and sealing kit for gland plates (supplied loose) 12 x 482.6 mm (19") fastener, 1 U, conductive (supplied loose) 25 multi-tooth screws, conductive (supplied loose) IPPC pallet
<b>Note:</b>	Depending on how and where it is sited, the door opening angle may vary for selected applications

<b>Basic material:</b>	Sheet steel
<b>Product features</b>	
<b>Dimensions:</b>	Width: 600 mm Height: 2000 mm Depth: 600 mm
<b>Installation height for components:</b>	42 U
<b>482.6 mm (19") version:</b>	front
<b>482.6 mm (19") attachment:</b>	with mounting bracket screw-fastened to the frame at the top and bottom
<b>Free mounting space to the 482.6 mm (19") level, front/rear:</b>	87 mm / 435 mm
<b>Load capacity:</b>	7500 N Static (max.) per enclosure to UL 2416: 6000 N
<b>Packs of:</b>	1 pc(s).
<b>EAN:</b>	4028177945531
<b>Customs tariff number:</b>	94032080
<b>ETIM 7.0:</b>	EC002499
<b>ETIM 6.0:</b>	EC002499
<b>eCl@ss 8.0/8.1:</b>	27180207
<b>eCl@ss 6.0/6.1:</b>	27180207
<b>Product description:</b>	VX IT, 19" mounting angles, standard, front, glazed door, WHD: 600 x 2000 x 600 mm, 42 HE, IP 55
<b>Approvals</b>	
<b>Approvals:</b>	UL + C-UL
<b>Declarations:</b>	Declaration of conformity