

Rittal – The System.

Faster – better – everywhere.

PSM Zero-U-Space – DK 7859.090

Date : Dec 17, 2020

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



PSM Zero-U-Space – DK 7859.090

created: 17.12.2020 on www.rittal.com/com-en

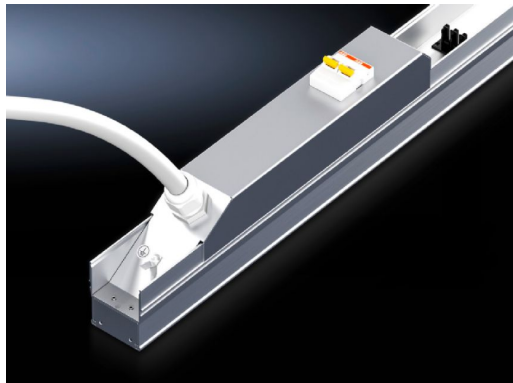

Product description

Description: Modular PDU for space-saving integration in the zero-U space between side panel and 482.6 mm (19") mounting level in 800 mm wide IT racks.

Material: Aluminium section, natural anodised

**Protection category
IP to IEC 60 529:** IP 20

Product features

Module slots (max.): 5

To fit: Height: > 2000 cm

Dimensions: Length: 1695 mm

Infeeds: Qty.: 1
Phases per infeed: 1~

**Length of connection
cable:** 3 m

Ambient conditions: Operating temperature: +5 °C...+45 °C
Ambient humidity (non-condensing): 10 % - 90 %

**Type of electrical
connection:** fixed/CEE

Rated current (max.): 32 A

Packs of: 1 pc(s).

Copper weight (kg per piece):	0
EAN:	4028177956643
Customs tariff number:	85369001
ETIM 7.0:	EC000215
ETIM 6.0:	EC000215
eCl@ss 8.0/8.1:	27371306
eCl@ss 6.0/6.1:	27371306
Product description:	DK modular PDU, PSM busbar, modular power distribution for vertical installation, in the Zero-U-Space for 800 mm wide IT racks, 1~, 32 A, length 1695 mm, module slots: 5, infeeds: 1, connection cable length: 3 m, CEE connector, for enclosure height 2000 mm, aluminium section, natural anodised