


Quad-Display Desktop Monitor Stand for 13" to 27" Flat-Screen Displays

MODEL NUMBER: DDR1327MQ

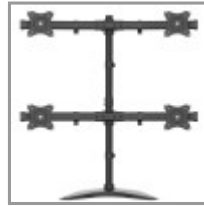

Mounts up to four 13 to 27 in. monitors on a single base to free up valuable space on your home or office desk, table or work area.

Features

Mounts Up to 4 Monitors on a Base Frees up valuable workspace on your desk, table or workstation Fits most flat-panel displays from 13 to 27 in. Mounts adjust independently for viewing angle Ideal for home and office use

Convenient One-Touch Adjustment 180° swivel and -45° to +45° tilt capability provides comfortable viewing Full 360° rotation for viewing in portrait or landscape orientation

Durable Metal Construction Each mount supports up to 17.6 lbs (7.9 kgs) Scratch-resistant powder-coated finish blends with any décor Mounting hardware included

VESA Compliance Supports the following VESA mounting hole patterns: 75 x 75 mm, 75 x 100 mm, 100 x 75 mm, and 100 x 100 mm

Highlights

- Monitor stand with heavy-duty base remains stable on your desk during adjustment
- -45° to +45° tilt, -15° to +15° swivel and 360° rotation helps you find the perfect angle
- Durable steel construction blends into any décor and supports up to 17.6 lbs (7.9 kgs) per monitor
- Display cables attach to pole to reduce clutter and keep cords organized
- VESA compliance ensures compatibility with 75x75 and 100x100 mounting patterns

Applications

- Lift as many as 4 monitors above your standing desk or workstation to free up valuable surface space
- Swivel, tilt and/or rotate your screens for the most comfortable viewing angle

System Requirements

- Up to 4 flat-screen monitors from 13 to 27 in. with 75 mm or 100 mm VESA mounting holes

Package Includes

- (4) VESA plate assemblies
- Upper pole
- Lower pole
- Pole connector
- Base
- (4) Mount arms
- (4) Arm cable guides



- (2) Pole cable guides
- (2) Locking head assemblies
- (4) End caps
- Base collar
- Hex key, 3 mm
- Hex key, 4 mm
- Hex key, 6 mm
- (4) Flat-head screws
- (16) M4 x 12 screws
- (16) M5 x 12 screws
- (16) D5 washers
- Owner's manual

Specifications

OVERVIEW	
UPC Code	037332257833
Device Compatibility	Monitor/HDTV
PHYSICAL	
Color	Black
VESA Pattern (mm)	100x100; 100x75; 75x100; 75x75
Degrees of Motion	-45/+45 Tilt; 180 Swivel; 360 Rotate
Material of Construction	Steel
Maximum Screen Size (cm)	68.6
Maximum Screen Size (in.)	27
Maximum Weight Capacity (kg)	8
Maximum Weight Capacity (lbs.)	17.6
Minimum Screen Size (in.)	13
Minimum Screen Size (cm)	33
Motion	Full
Mounting Location	Desktop
Number of Displays	4
Shipping Dimensions (hwd / cm)	46.99 x 33.53 x 13.72
Shipping Dimensions (hwd / in.)	18.50 x 13.20 x 5.40



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

Shipping Weight (kg)	9.54
Shipping Weight (lbs.)	21.04
Unit Dimensions (hwd / cm)	81.8 X 80.5 X 31.5
Unit Dimensions (hwd / in.)	32.3 X 31.7 X 12.4
Unit Weight (kg)	3.04
Unit Weight (lbs.)	6.7
FEATURES & SPECIFICATIONS	
Tools Necessary	Yes
SPECIAL FEATURES	
Cord Management	No
Security Lock	No
STANDARDS & COMPLIANCE	
Approvals	RoHS3, REACH
WARRANTY	
Product Warranty Period (Worldwide)	5-year limited warranty

© 2021 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies: <https://www.tripplite.com/products/product-certification-agencies>