

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1200850005](#)
Status: **Active**
Overview: [Brad Ultra-Lock Connection System](#)
Description: Ultra-Lock (M12) Single Keyway with PG9 Cable Fitting, Male, 4 Pole, Straight, Cable Diameter 4.10-8.10mm

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837

General

Product Family Field Attachable / Accessories
Series [120085](#)
Approvals N/A
IP Rating IP69K
Material - Contact Brass
Overview [Brad Ultra-Lock Connection System](#)
Product Name Ultra-Lock (M12)
Type Field Attachable Connector
UPC 78678897637

Physical

Cable Diameter 4.10 - 8.10mm (.161-.319")
Coupling Type Push to Lock
Diagnostics / LEDs No
Diagnostics Port No
Gender Male
Keyway Single
Material - Connector Body PA
Material - Coupling Nut Nickel-plated Brass
Material - Plating Mating Gold
Net Weight 1.000/g
Orientation Straight
Poles 4
Temperature Range - Operating -25°C to +90°C
Wire Size AWG 18

Electrical


Current - Maximum per Contact 4.0A
Voltage - Maximum 250V AC / 300V DC

Material Info

Engineering Number WA4006-32

Reference - Drawing Numbers

Sales Drawing SD-120085-002

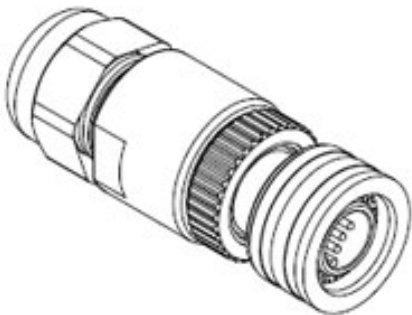

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China RoHS

China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[120085](#) Series