

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2210503466](#)
Status: **Active**
Overview: mPm DIN Valve Connectors
Description: mPm DIN Valve Connector, Form A - 18mm, 2 Pole, to 5.0m PUR UL Cable Pigtail, Yellow LED, Black Integrated Gasket, 18 AWG, 24V

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Industrial Cordsets
Series	221050
Connector End A	Brad mPm DIN A - 18mm
Connector End B	Pigtail
IP Rating	IP67
Material - Contact	Brass
Overview	mPm DIN Valve Connectors
Product Name	mPm
Protocol	EtherNet
Region	America, Europe
Type	Single Ended
UPC	78172529121

Physical

Cable Diameter	5.72mm (.225")
Cable Length	5.0m (16.40')
Color - Cable Jacket	Black
Coupling Style	Threaded
Gender	Male-Pigtail
Keyway	None
LED Indicator	Yellow
Material - Cable Jacket	PUR UL
Material - Connector Body	Polypropylene
Material - Coupling Nut	N/A
Material - Plating Mating	N/A
Net Weight	331.575/g
Orientation	90° to Pigtail
Poles	2
Temperature Range - Operating	-40°C to +90°C
Wire Size AWG	18
Wire/Cable Type	N/A

Electrical


Current - Maximum per Contact	N/A
Voltage - Maximum	24V

Material Info

Engineering Number	E452B3A5001PS0H
--------------------	-----------------

Reference - Drawing Numbers

Sales Drawing	1210502000-000, SD-121050-001-001
---------------	-----------------------------------

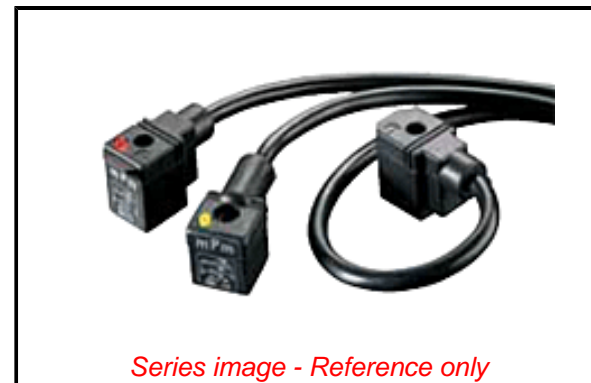

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 7(c)-I

REACH SVHC

Contained Per - D(2020)4578-DC (25 June 2020)
lead

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[221050 Series](#)