


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1200850012](#)
Status: **Active**
Overview: [Brad Ultra-Lock Connection System](#)
Description: Ultra-Lock (M12) Single Keyway with PG7 Cable Fitting, Female, 5 Pole, Straight, Cable Diameter 3.30-6.60mm

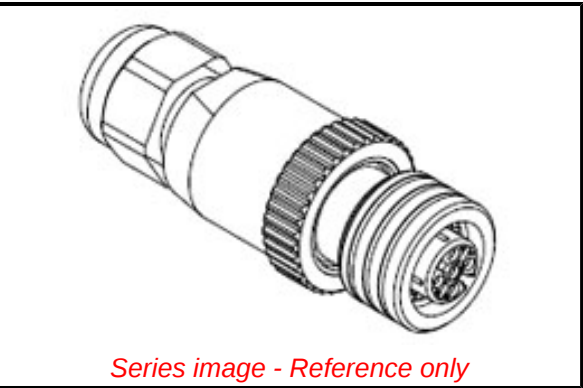

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification	
CSA	LR6837
General	
Product Family	Field Attachable / Accessories
Series	120085
Approvals	N/A
IP Rating	IP69K
Material - Contact	Brass
Overview	Brad Ultra-Lock Connection System
Product Name	Ultra-Lock (M12)
Type	Field Attachable Connector
UPC	78678897649
Physical	
Cable Diameter	3.30-6.60mm (.130-.260")
Coupling Type	Push to Lock
Diagnostics / LEDs	No
Diagnostics Port	No
Gender	Female
Keyway	Single
Material - Connector Body	PA
Material - Coupling Nut	Nickel-plated Brass
Material - Plating Mating	Gold
Net Weight	17.930/g
Orientation	Straight
Poles	5
Temperature Range - Operating	-25°C to +90°C
Wire Size AWG	18
Electrical	
Current - Maximum per Contact	4.0A
Voltage - Maximum	30V AC / 36V DC
Material Info	
Engineering Number	WA5000-31
Reference - Drawing Numbers	
Sales Drawing	SD-120085-004

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China RoHS

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[120085](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION