


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1200850013](#)
Status: **Active**
Overview: [Brad Ultra-Lock Connection System](#)
Description: Ultra-Lock (M12) Single Keyway with PG9 Cable Fitting, Female, 4 Pole, Straight, Cable Diameter 4.10-8.10mm

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Field Attachable / Accessories
Series	120085
Approvals	N/A
IP Rating	IP69K
Material - Contact	Brass
Overview	Brad Ultra-Lock Connection System
Product Name	Ultra-Lock (M12)
Type	Field Attachable Connector
UPC	78678897651
Physical	
Cable Diameter	4.10 - 8.10mm (.161-.319")
Coupling Type	Push to Lock
Diagnostics / LEDs	No
Diagnostics Port	No
Gender	Female
Keyway	Single
Material - Connector Body	PA
Material - Coupling Nut	Nickel-plated Brass
Material - Plating Mating	Gold
Net Weight	20.520/g
Orientation	Straight
Poles	4
Temperature Range - Operating	-25°C to +90°C
Wire Size AWG	18
Electrical	
Current - Maximum per Contact	4.0A
Voltage - Maximum	250V AC / 300V DC
Material Info	
Engineering Number	WA4000-32
Reference - Drawing Numbers	
Sales Drawing	SD-120085-005

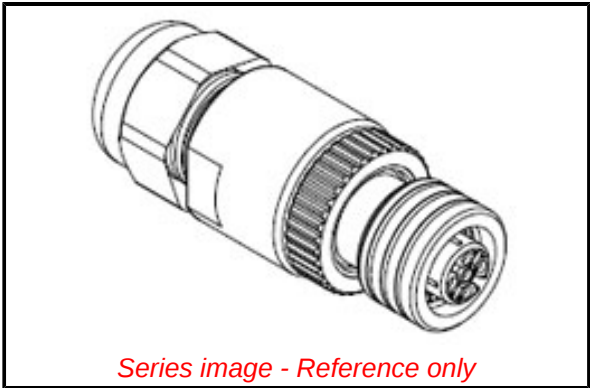

EU ELV Not Relevant	
EU RoHS Compliant with Exemption 6(c) REACH SVHC Not Reviewed Halogen-Free Status Not Low-Halogen	China RoHS
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[120085](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION