

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1200850003

Status:


Active

Overview:

Brad Ultra-Lock Connection System

Description:

Ultra-Lock (M12) Single Keyway with PG7 Cable Fitting, Male, 4 Pole, Straight, Cable Diameter 3.30-6.60mm

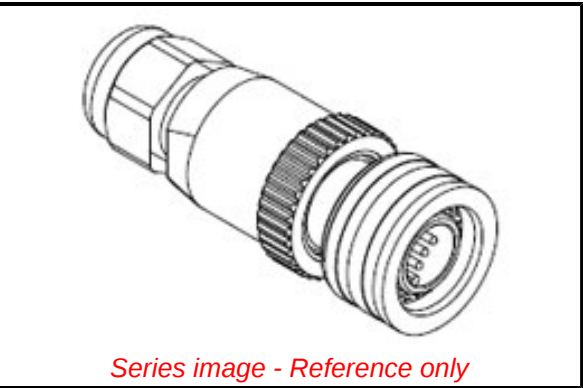

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR6837
General	
Product Family	Field Attachable / Accessories
Series	120085
Approvals	N/A
IP Rating	IP69K
Material - Contact	Brass
Overview	Brad Ultra-Lock Connection System
Product Name	Ultra-Lock (M12)
Type	Field Attachable Connector
UPC	78172553190
Physical	
Cable Diameter	3.30-6.60mm (.130-.260")
Coupling Type	Push to Lock
Diagnostics / LEDs	No
Diagnostics Port	No
Gender	Male
Keyway	Single
Material - Connector Body	PA
Material - Coupling Nut	Nickel-plated Brass
Material - Plating Mating	Gold
Net Weight	20.000/g
Orientation	Straight
Poles	4
Temperature Range - Operating	-25°C to +90°C
Wire Size AWG	18
Electrical	
Current - Maximum per Contact	4.0A
Voltage - Maximum	250V AC / 300V DC
Material Info	
Engineering Number	WA4006-31
Reference - Drawing Numbers	
Sales Drawing	SD-120085-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

120085 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION