

# WEISER®

## HomeConnect 620™

KEYPAD CONNECTED SMART LOCK

With Z-Wave® 700 Chipset



### Features

- 10-Button keypad with one-touch locking
- Featuring Smartkey® Security Technology
- Sleek, all metal design
- Z-Wave® 700 for enhanced network security, network pre-enrollment, and extended wireless range and battery life
- Backward compatible with existing Z-Wave panels and hubs
- S2 Secure Network Enrollment
- SmartStart Network Pre-Enrollment

### User Codes

- 250 user codes
- Control when people have access with customizable user code schedules
- MasterCode security for improved feature management

### Connected Benefits

- Lock/Unlock your doors from anywhere
- View lock status and receive notifications of your lock's activity
- Connect to other devices in the home and create scenes driven by the door lock

**CANADA'S #1 SELLING LOCK BRAND\***

Weiser is a trademark of Spectrum Brands, Inc. © 2020 Spectrum Brands, Inc.

## Specifications

### Electrical:

<b>Input Power</b>	6V (4 x AA alkaline batteries)
--------------------	--------------------------------

### Mechanical:

<b>Door Prep</b>	1 1/2" & 2 1/8" diameter bore hole & 1" deep latch hole
<b>Backset</b>	Adjustable 2 3/8" or 2 3/4"
<b>Door Thickness</b>	1 3/8" - 2" automatic adjustment
<b>Faceplates</b>	1" x 2 1/4" round corner standard
<b>Strikes</b>	Round corner strike 1 1/8" x 2 3/4"
<b>Latch</b>	Round corner adjustable 2 3/8" x 2 3/4"
<b>Bolt</b>	1" throw, steel deadbolt
<b>Door Handing</b>	Reversible
<b>Cylinder</b>	SmartKey® Keyway

### Environmental:

<b>Temperature Range</b>	Exterior: -40°F to 150°F Interior: 32°F to 140°F
<b>Humidity</b>	Exterior: 100% condensing Interior: 30% - 95% non-condensing

## Finishes



Satin Nickel 15  
9GED18000-026



Venetian Bronze 11P  
9GED18000-027



Polished Brass 3  
9GED18000-028



Satin Nickel 15  
9GED18000-029




Polished Chrome 26  
9GED18000-030




Matte Black 514  
9GED18000-031

## Dimensions

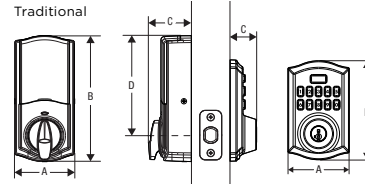

	Interior	Exterior
<b>A</b>	2 23/32" (69.1 mm)	2 13/16" (71.43 mm)
<b>B</b>	2 23/32" (69.1 mm)	4 9/16" (115.887 mm)
<b>C</b>	1 15/16" (49.5 mm)	1 1/4" (31.75 mm)
<b>D</b>	4 19/32" (116.5 mm)	---

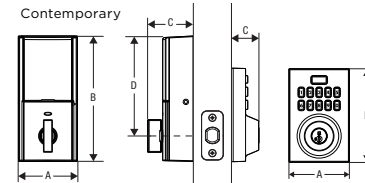

	Interior	Exterior
<b>A</b>	2 23/32" (69.1 mm)	2 25/32" (70.64 mm)
<b>B</b>	5 25/32" (146.6 mm)	4 5/16" (109.53 mm)
<b>C</b>	2 1/8" (53.97 mm)	1 1/4" (31.75 mm)
<b>D</b>	4 1/2" (114.3 mm)	---

## Easy Installation

- Replaces existing door hardware with just a screwdriver
- No hard wiring needed
- Operates on 4 x AA alkaline batteries

## Innovative Security

- BHMA Grade 2 certified
- Full 128-bit encryption security
- Features SmartKey® Security Re-Key Technology with BumpGuard™ Protection
- Revolutionary tapered deadbolt design—enables misaligned doors to lock without pulling and pushing your door shut
- Supports S2 Secure Network Enrollment

FINISH AND  
**LIFETIME  
WARRANTY**  
MECHANICAL  
ONE YEAR  
ELECTRONIC WARRANTY

# WEISER®

www.weiserlock.com • 1-800-501-9471  
Weiser is a trademark of Spectrum Brands, Inc. © 2020 Spectrum Brands, Inc.