



OVERVIEW

The Call Button Kit with Microphone (BTN-KIT-MIC-ND) easily connects via RJ25 cable to IP compatible devices and enables two-way communication.

AUDIO FUNCTIONALITY



Intercom, page, or all-call
Trigger pre-programmed text,
or privacy mode

MICROPHONE



Hands-free talk back
Monitoring

BUTTON LED



Illuminates when
microphone is active

NOTIFICATION



Trigger alerts that activate other
devices, such as a strobe or
electronic lock

SIP INTEGRATION



Enable SIP calls
Dial out pre-programmed
internal extensions and
external phone numbers

SOFTWARE



Diagnostic software included
Compatible with third-party
software, including InformaCast,
Revolution, and Cisco CallManager

DUAL COMMANDS



Program button push and
release / push and hold modes
Accommodates up to two
extensions or phone numbers

SOLUTIONS

- Paging
- Intercom
- Emergency notification

ADDITIONAL FEATURES

- Built-in web server
- Requires RJ25 cable (6P6C)

MOUNTING

- Standard junction box required for mounting

SOFTWARE

The BTN-KIT-MIC-ND integrates easily with third-party mass notification software, as well as SIP and VoIP phone systems, enabling a facility to take advantage of all the device capabilities. The device also comes with diagnostic software (compatible to run alongside third-party software), and an on-board web server interface, both which provide the ability to monitor and troubleshoot the ANetD devices on the network.

Third-Party Software

- InformaCast (Singlewire)
 - Revolution (Syn-Apps)
 - IPSession (IPCelerate)
 - MessageNet Systems
 - BellComander (Acro Vista)
- And more!

VoIP Phone Systems


- Cisco CallManager
 - Mitel
 - Avaya
 - 3CX
 - Polycom
- And more!

IPClockWise


- Diagnostic tool included with device purchase
- Complements investment in third-party software
- Developed and supported by Advanced Network Devices

DIMENSIONS

Front

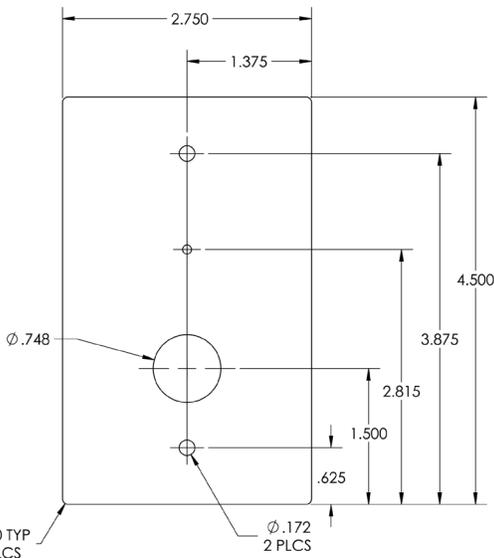

Side

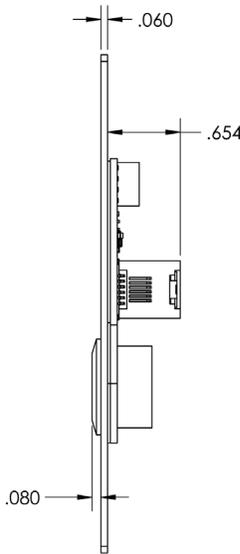

COMPATIBILITY CHART

AND-BTN-KIT-1

- IPSWDHD-MW
- IPCSHD-MB
- IPSWD-RWB
- IPCSS-RWB / IPCSS-RWB-MB
- IPCDS-RWB-U
- IPSIGNL-RWB
- IPCSL-RWB
- IPSW-SM / IPSWS-FM... (MAC Address **20:46:f9:09:xx:xx** and lower)
- IPSCM..... (MAC Address **20:46:f9:09:xx:xx** and lower)
- ZONEC2

BTN-KIT-MIC-ND

- IPSCM..... (MAC Address **20:46:f9:0a:xx:xx** and higher)
- IPSCM-RMe
- IPSW-SM / IPSWS-FM.. (MAC Address **20:46:f9:0a:xx:xx** and higher)
- IPSWDHD-MW
- IPCSHD-MB

Note: IPSWS-SM-O is unsupported
Call tech support regarding discontinued models

SPECIFICATIONS

BTN-KIT-MIC-ND

FACEPLATE MATERIAL	16-gauge brushed stainless steel
ELECTRICAL LIFE	200,000 cycles
POWER CONNECTION	RJ25 cable (6P6C)
SWITCH FUNCTION	Momentary ON
OPERATING TEMPERATURE	-20° to 50° C (-4° - 131° F)
CIRCUIT	SPST
MAX DISTANCE FROM ENDPOINT	Up to 25ft
INSTALLATION DEPTH	1" (25.4 mm)
DIMENSIONS	2.75" W x 4.5" H
WEIGHT	4 oz
WARRANTY	2 Year Limited

Due to continual product development, specifications are subject to change without notice.

