


Small cooling units

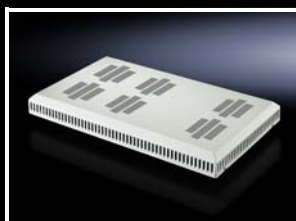

Fan mounting plate

for VX IT, TE

For active ventilation. The unit may optionally be extended with additional fans.

Applications:

- For use in the cut-out integrated into the roof plate

Colour:

- RAL 7035

Supply includes:

- 1 fan unit
- 2 fans
- 1 thermostat
- Connection cable, open-ended
- Assembly parts

Note:

- The noise level given refers to the first fan
- Connection via distributor box or country-specific connector



Accessories:

- Fan expansion kit, see page 790

W x H x D mm	Installation options	No. of fans	Number of fans (max.)	Air through-put per fan m ³ /h	Output per fan W	Rated operating voltage V, ~, Hz	Operating temperature range	Noise level per fan dB(A)	Packs of	Model No.
200 x 59 x 550	In VX IT with W x D (mm): 600 x 600 / 600 x 800 / 600 x 1000 / 600 x 1200 / 800 x 600	2	3	160 / 180	15 / 14	230, 1~, 50/60	+5 °C...+55 °C	37	1 pc(s).	5502.010
340 x 54 x 550	In VX IT with W x D (mm): 800 x 800 / 800 x 1000 / 800 x 1200 In TE 8000 with W x D (mm): 600 x 600 / 600 x 800 / 600 x 1000 / 800 x 600 / 800 x 800 / 800 x 1000	2	6	160 / 180	15 / 14	230, 1~, 50/60	+5 °C...+55 °C	37	1 pc(s).	5502.020



Fan expansion kit

For use as a stand-alone fan, and for upgrading various fan units or to supplement the fan mounting plate.

Supply includes:

- Fan
- Connection cable (0.61 m)
- Assembly parts

W x H x D mm	Air through-put (unimpeded air flow) m ³ /h	Rated operating voltage V, ~, Hz	Power consumption W	Operating temperature range	Noise level dB(A)	Packs of	Model No.
119 x 119 x 38	160 / 180	230, 1~, 50/60	15 / 14	-10 °C...+55 °C	37 / 37	1 pc(s).	7980.000
119 x 119 x 25	108 / 120	230, 1~, 50/60	14 / 12	-20 °C...+70 °C	34 / 34	1 pc(s).	7980.100
119 x 119 x 38	184	48 (DC)	7.7	-20 °C...+70 °C	43	1 pc(s).	7980.148