

4K 60Hz KVM

Model : CV-801K



Benefits

- 4K KVM with 8 HDMI USB ports in 1U
- 4K KVM cables support DP & HDMI video input
- USB hub port share peripheral devices among computers
- Local console & KVM ports support resolution 4K, 2K and 1080p.
- Multi-platform for PC, server, blade server & SUN / MAC
- Port switching via front button & keyboard hotkeys
- Hot pluggable, no software or drivers required

Options

- DC power options : 12V / 24V / 48V / 125V



CK-6P
DP KVM cable, 6 ft
4K 60Hz



CK-6H
HDMI KVM cable, 6 ft
4K 60Hz


KVM Port

Port # :	8
Connector :	HDMI 2.0 + USB-B (Video + KB / MS)
Resolution :	16 : 9 - max. 3840 x 2160@60Hz 16 : 10 - max. 1920 x 1200@60Hz 4 : 3 - max. 1600 x 1200@60Hz

Local Console

Keyboard / Mouse :	2 x USB-A
Video :	1 x HDMI 2.0
Resolution :	16 : 9 - max. 3840 x 2160@60Hz 16 : 10 - max. 1920 x 1200@60Hz 4 : 3 - max. 1600 x 1200@60Hz

Local console & KVM port connection

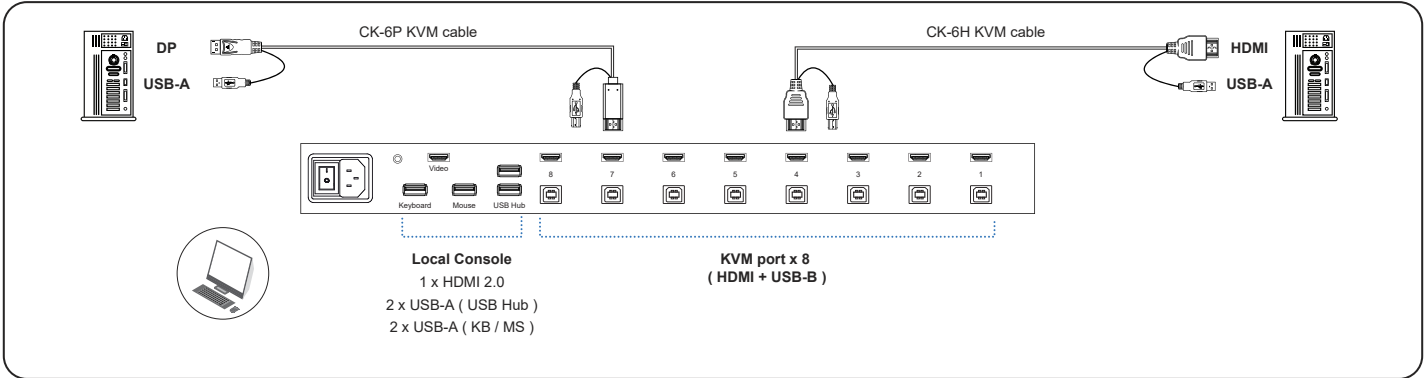

Management

Port switching	Front button & keyboard hotkeys
----------------	---------------------------------

Power

Input	Auto-sensing 100 to 240VAC, 50 / 60Hz
Consumption	Max. 10W

Compatibility

Hardware	HP / IBM / Dell PC, Server and Blade Server SUN / Mac
OS support	Windows / Linux / Unix / Mac OS

Compliance

Safety	FCC & CE certified
Environment	RoHS3 & REACH compliant

Environment

Operating temp.	0 to 55°C degree
Storage temp.	-20 to 60°C degree
Operating humidity	20~90%, non-condensing
Storage humidity	5 ~90%, non-condensing
Operating altitude	16,000 ft
Non-operating altitude	40,000 ft
Shock	10G acceleration (11ms duration)
Vibration	10~300Hz 0.5G RMS random vibration

Physical

Product (W x D x H)		443 x 171 x 44 mm
		17.4 x 6.7 x 1.73 inch
Packing (W x D x H)		500 x 400 x 90 mm
		19.7 x 15.7 x 3.5 inch
Weight	Net	2.5 kg / 5.5 lb
	Gross	5.4 kg / 11.9 lb
Chassis color		Dark
Chassis materials		Steel