


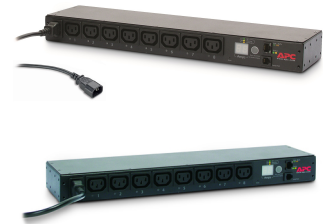

APC AP7920B power distribution unit (PDU) 8 AC outlet(s) 0U/1U Black



Brand : APC

Product code: AP7920B

Product name : AP7920B

1U, 12A/208V, 10A/230V, 50/60 Hz, 8x IEC 320 C13, IEC-320 C14, 445 x 108 x 44 mm, 2270 g
APC AP7920B. PDU types: Metered, Switched, Rack capacity: 0U/1U, Mounting: Horizontal/Vertical. AC outlets quantity: 8 AC outlet(s), AC outlet types: C13 coupler, Power plug: C14 coupler. Cable length: 1.98 m, Certification: cUL Listed, CE, CSA, EN 55022 Class A, EN 55024, EN 61000-3-2, EN 61000-3-3, GOST, IRAM, MIC, UL.... Monitoring: Current, Power, Voltage, Outlet control: Lock-out, Recycle, Turn off, Turn on. Nominal input voltage: 200-230 V, Maximum current: 10 A, AC input frequency: 50 - 60 Hz



Design		Power	
PDU types *	Metered, Switched	Maximum input current per phase	10 A
Rack capacity *	0U/1U	Maximum total current draw per phase	10 A
Mounting	Horizontal/Vertical	Maximum power	2300 W
Product colour	Black	Weight & dimensions	
Ports & interfaces		Dimensions (WxDxH)	445 x 108 x 44 mm
AC outlets quantity *	8 AC outlet(s)	Weight	2.27 kg
Power plug	C14 coupler	Packaging data	
AC outlet types *	C13 coupler	Package dimensions (WxDxH)	470 x 343 x 70 mm
Input connection type	IEC-320 C14	Package weight	3.45 kg
Features		Packaging content	
Cable length	1.98 m	Packaging content	Installation Guide, Rack Mounting Brackets, User Manual
Certification	cUL Listed, CE, CSA, EN 55022 Class A, EN 55024, EN 61000-3-2, EN 61000-3-3, GOST, IRAM, MIC, UL 60950, UL Listed, VDE, VCCI, REACH	Operational conditions	
Management features		Operating temperature (T-T)	0 - 45 °C
Monitoring	Current, Power, Voltage	Storage temperature (T-T)	-25 - 65 °C
Outlet control	Lock-out, Recycle, Turn off, Turn on	Operating relative humidity (H-H)	0 - 95%
Power		Storage relative humidity (H-H)	0 - 95%
Nominal input voltage *	200-230 V	Operating altitude	0 - 3000 m
AC input frequency	50 - 60 Hz	Non-operating altitude	1 - 15000 m
Maximum current *	10 A	Technical details	
Nominal output voltage	208-230 V	Sustainability certificates	RoHS
Load capacity	2300 VA		



731304331612

Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.