


# Category 3

## CMR/CMP 2-Pair - 400-Pair

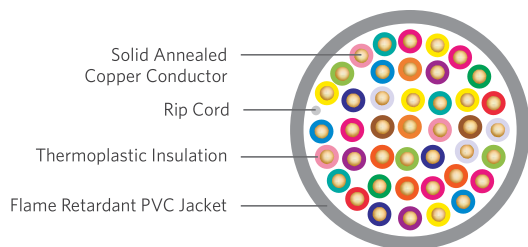

### SPECIFICATIONS

Pair Count	Available in 2-pair up to 400-pair
Conductor	Solid annealed copper
AWG (mm)	24 (0.51)
Insulation	Thermoplastic
Jacket	CMR: Flame retardant (FR) PVC CMP: FR, low smoke PVC
Characteristic Impedance Ohms	100 ± 15
Performance Compliance	UL® 444 CSA C22.2 No. 214-08 UL 1666 NFPA 262 ANSI/TIA-568-C.2 ANSI/ICEA S-90-661-2012 Article 800, NEC (NFPA 70) RoHS-compliant/RoHS 2-compliant
NRTL Programs	UL, c(UL) Listed CMR UL, c(UL) Listed CMP

### PRODUCT DESCRIPTION

The ideal choice for LAN transmission with specified bandwidth up to 16 MHz. These cables are used for voice and data communications and can handle application bandwidths up to 16 MHz. Other uses for these cables include indoor use on customer premises for the interconnection of telephone key systems, PBX and intercom systems. Product is offered for both plenum (CMP) and riser (CMR) applications.

### APPLICATIONS

- 4 Mbps token ring (IEEE 802.5)
- Analog voice
- 10 Mbps 10BASE-T Ethernet (IEEE 802.3)
- Telecommunications closet wiring

### FEATURES

- CMR and CMP constructions use extremely flexible, FR-PVC jacket
- Jacket color options
- Band marked or striped insulated conductors

### BENEFITS

- Easier and less time-consuming installations, no kinking of outer jacket
- Improves backbone sub-system identification, reduces labor and mistakes
- Reduces termination time and improves circuit identification

## PART NUMBERS AND PHYSICAL CHARACTERISTICS

Listing	Part Number	Pair Count	Jacket Color	Nominal Diameter in (mm)	Approx. Weight lbs/kft (kg/km)	Package	Packages per Pallet
CMR	18-042-13	2	Beige	0.12 (3.1)	9 (13)	1,000' POP™ box	45
CMR	18-042-33	2	Gray	0.12 (3.1)	9 (13)	1,000' POP box	45
CMR	18-141-13	3	Beige	0.14 (3.5)	12 (18)	1,000' POP box	45
CMR	18-141-33	3	Gray	0.14 (3.5)	12 (18)	1,000' POP box	45
CMR	18-241-13	4	Beige	0.16 (3.9)	15 (22)	1,000' POP box	45
CMR	18-241-23	4	Blue	0.16 (3.9)	15 (22)	1,000' POP box	45
CMR	18-241-33	4	Gray	0.16 (3.9)	15 (22)	1,000' POP box	45
CMR	18-241-43	4	White	0.16 (3.9)	15 (22)	1,000' POP box	45
CMR	18-341-13	6	Beige	0.19 (4.8)	22 (32)	1,000' POP box	45
CMR	18-341-33	6	Gray	0.19 (4.8)	22 (32)	1,000' POP box	45
CMR	18-872-13	12	Beige	0.27 (6.9)	47 (71)	1,000' Plywood reel	16
CMR	18-872-33	12	Gray	0.27 (6.9)	47 (71)	1,000' Plywood reel	16
CMR	18-475-13	25	Beige	0.38 (9.6)	92 (137)	1,000' Plywood reel	12
CMR	18-499-13	25	Beige	0.38 (9.6)	92 (137)	Cut to length	1
CMR	18-475-33	25	Gray	0.38 (9.6)	92 (137)	1,000' Plywood reel	12
CMR	18-499-33	25	Gray	0.38 (9.6)	92 (137)	Cut to length	1
CMR	18-579-13	50	Beige	0.56 (14.2)	187 (279)	1,000' Plywood reel	4
CMR	18-599-13	50	Beige	0.56 (14.2)	187 (279)	Cut to length	1
CMR	18-579-33	50	Gray	0.56 (14.2)	187 (279)	1,000' Plywood reel	4
CMR	18-599-33	50	Gray	0.56 (14.2)	187 (279)	Cut to length	1
CMR	18-789-13	100	Beige	0.74 (18.7)	361 (538)	Cut to length	1
CMR	18-789-33	100	Gray	0.74 (18.7)	361 (538)	Cut to length	1
CMR	18-D99-33	150	Gray	0.92 (23.4)	541 (807)	Cut to length	1
CMR	18-A99-33	200	Gray	1.05 (26.6)	711 (1,060)	Cut to length	1
CMR	18-B99-33	300	Gray	1.27 (32.2)	1,049 (1,564)	Cut to length	1
CMR	18-C99-33	400	Gray	1.45 (36.9)	1,386 (2,067)	Cut to length	1
CMP	18-041-36	2	Gray	0.13 (3.3)	10 (15)	1,000' POP box	45
CMP	18-141-36	3	Gray	0.15 (3.7)	14 (20)	1,000' POP box	45
CMP	18-241-26	4	Blue	0.16 (4.2)	17 (26)	1,000' POP box	45
CMP	18-241-36	4	Gray	0.16 (4.2)	17 (26)	1,000' POP box	45
CMP	18-241-46	4	White	0.16 (4.2)	17 (26)	1,000' POP box	45
CMP	18-241-56	4	Green	0.16 (4.2)	17 (26)	1,000' POP box	45
CMP	18-341-36	6	Gray	0.20 (5.0)	24 (37)	1,000' POP box	45
CMP	18-341-46	6	White	0.20 (5.0)	24 (37)	1,000' POP box	45
CMP	18-872-46	12	White	0.30 (7.6)	49 (73)	1,000' Plywood reel	16
CMP	18-475-36	25	Gray	0.43 (10.9)	114 (171)	1,000' Plywood reel	12
CMP	18-499-36	25	Gray	0.43 (10.9)	114 (171)	Cut to length	1
CMP	18-475-46	25	White	0.43 (10.9)	114 (171)	1,000' Plywood reel	12
CMP	18-499-46	25	White	0.43 (10.9)	114 (171)	Cut to length	1
CMP	18-579-36	50	Gray	0.60 (15.3)	227 (339)	1,000' Plywood reel	4
CMP	18-599-36	50	Gray	0.60 (15.3)	227 (339)	Cut to length	1
CMP	18-799-36	100	Gray	0.84 (21.3)	446 (665)	Cut to length	1
CMP	18-799-46	100	White	0.84 (21.3)	446 (666)	Cut to length	1
CMP	18-A99-36	200	Gray	1.16 (29.4)	850 (1,268)	Cut to length	1
CMP	18-B99-36	300	Gray	1.44 (36.7)	1,315 (1,960)	Cut to length	1
CMP	18-B99-46	300	White	1.44 (36.7)	1,315 (1,961)	Cut to length	1
CMP	18-C99-36	400	Gray	1.64 (41.7)	1,720 (2,565)	Cut to length	1

UL is a registered trademark of UL LLC.