


4K ULTRA Hi-DEFINITION PROFESSIONAL MONITOR

4K UHD LED

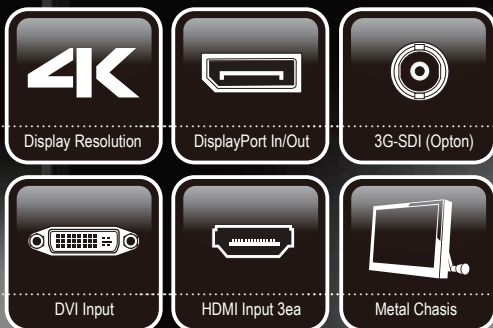

4K27DHDN

BUILT TO RUN 24 X 7 X 365 CONTINUOUSLY

OVERVIEW

Our newly developed 27.0 inch professional monitor features a 4K 3840 x 2160 resolution. These monitors accept 4K signals at the multiple and various interfaces: DisplayPort 60p, HDMI 60p. There is also optional 3G or 6G-SDI signal support.

FEATURES

- » High Resolution(3840x2160) Panel with LED Backlight
- » Anti-Reflection Front Coating
- » Full 60fps Frame Rate
- » Multi-Input Interface: Display Port, HDMI, DVI, VGA, SDI(Optional)
- » Dynamic Contrast: ON / OFF
- » Wide Viewing Angle
- » 3D De-interlace
- » Industrial Grade Metal Cabinet
- » Rotation Screen/OSD menu (90/180/270)

Thin Bezel

ANTI-Reflection

Safe Square Stand



Built to run 24 x 7 x 365
Continuously


SPECIFICATIONS

4K27DHDN	
Display	
Screen Size	27.0 Inch
Max. Resolution	3840 x 2160
Pixel Pitch	0.1554 x 0.1554mm
Brightness	350cd/m ²
Contrast Ratio	1300 : 1
Aspect Ratio	16 : 9
Viewing Angle (H/V)	178° / 178°
Display Color	1.07 Billion
Response Time	< 14.0ms
Video System	NTSC / PAL
Interface	
Display Port In/ Out	1 / 1
HDMI Input	3
DVI In	1
VGA In	1
3G-SDI In / Out	Option
Audio Out (3.5 Ø stereo)	1
Transmitter	
Remote Control	Yes
Audio	
Built-in Speakers	Yes (5W x 2)
Features	
Multi Display Function	PIP/PBP/TRI/QUAD
Deinterlacing	Yes
Noise Reduction Control (NR)	Yes
Aspect Ratio	Yes
Dynamic Contrast	Yes (On / Off)
Gamma Selection	Yes (On / Off)
General	
Outline Dimension (W x H x D)	24.07" x 17.09" x 6.50"
Net Weight	8.0kg (17.63 lbs)
Material / Color	Metal / Black
Desk Top Stand	Foot Type
Warranty	3 Years Parts & Labor
Consumption	< 45W
Electrical Ratings	DC 12V
Operating Temperature	0° ~ 50° C / 32° ~ 122° F
Storage Temperature	-20° ~ 60° C / -4° ~ 140° F
Mounts	
VESA™ Mount Size	100 x 100mm
Wall	WB-5, WB-10, WB-30, WB-31
Ceiling	CMK-01

*Design and specifications are subject to change without notice

INTERFACE


<BOTTOM>

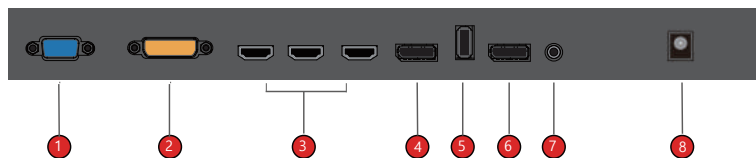

<BOTTOM>

- ① **VGA** : VGA signal Input
- ② **DVI** : DVI signal Input
- ③ **HDMI1~3** : HDMI1~3 Input
- ④ **DP** : DP signal Input
- ⑤ **USB** : FW Update Input
- ⑥ **DP** : DP signal Output
- ⑦ **Audio** : Audio Line Output
- ⑧ **Power** : DC 12V

DIMENSIONS

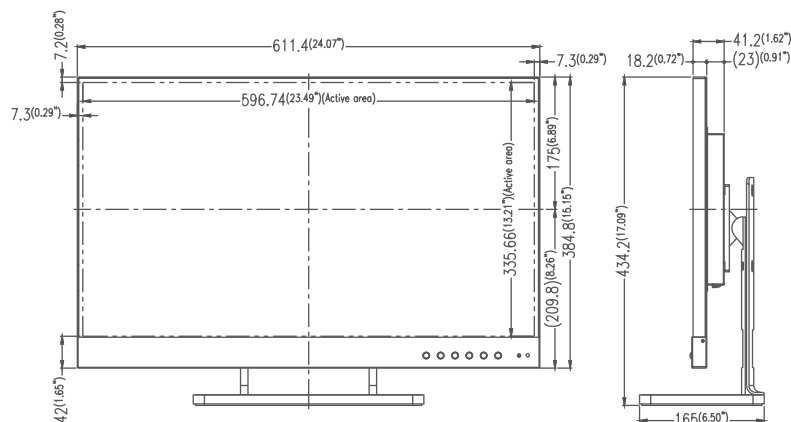

OPTIONAL MOUNTS

PRODUCT VIEW



Front View



Side View

