

Security Rated 17" LED Monitor

HDMI, VGA & BNC Video Inputs, PC Audio In/Output

LSM17ST




FEATURES:

- ◆ NDAA & TAA Compliant
- ◆ 5:4 Aspect Ratio
- ◆ 1280 x 1024 Max Resolution
- ◆ Active Display, Diagonal 17" (43.18cm)
- ◆ Dual HDMI Inputs
- ◆ VGA & Looping BNC Input
- ◆ Low Power Consumption
- ◆ Includes HDMI & VGA Cables
- ◆ Super Fast 5ms Response Time
- ◆ 3D Comb Filter & 3D De-Interlace
- ◆ 3D Digital Noise Reduction
- ◆ RCA & PC Audio Inputs
- ◆ Full OSD Control of All Monitor Functions
- ◆ Vesa Mounting (75 x 75)
- ◆ LED Backlight
- ◆ CE & FCC Certifications

PACKAGE CONTENTS:

- 1. – 1.8M HDMI Cable
- 1. – 1.8M VGA Cable
- 1. – 1.5M 3.5mm Stereo Audio Cable
- 1. – Power Supply w/ 1.8M Power Cord
- 1. – Monitor Stand
- 1. – User Manual

REAR PANEL CONNECTIONS:

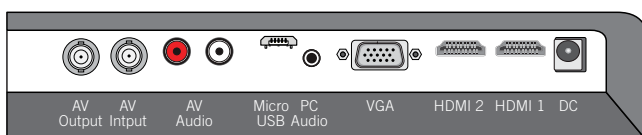

SPECIFICATION	LSM17ST
Video System	NTSC/PAL (Auto Sensing)
Max Resolution	1280 x 1024 (Native)
Supported Resolutions	720x400; 640x480; 800x600; 1024x768; 1280x1024; 1920x1080 (Upscaled)
Video Connections	HDMI, VGA, BNC Input/Output
3D Comb Filter	Yes
3D De-Interlace	Yes
OSD (On Screen Display)	Yes
Backlight	LED
Active Display Area	Diagonal 17" (43.18cm)
Impedance	75 OHM Self Terminating
Video Input Signals	HDMI, VGA, Composite BNC
Aspect Ratio	5:4
Pixel Pitch	0.264
Color Depth	16.7 Million Colors
Brightness	300 c/dm2
Contrast Ratio	1000:1
Viewing Angle (H/V)	170°/160°
Response Time	5ms
Auto Adjustment	Yes
Certificates	CE, FCC, UL
Languages	English, French, Spanish, German, Japanese, Dutch, Russian, Italian
Input Voltage	External 12Volt DC / 3 Amp
Power Consumption	<25W
Audio Connections	PC Audio (3.5mm Stereo) for VGA & BNC Input
Speakers	8Ω, 2 Watt per Channel
Dimensions with stand (H x W x D)	385 x 372 x 164mm
Weight (with stand)	2.98Kgs(6.56lbs)
Vesa Mounting	Yes (75 x 75)
Operating Temperature	32° ~ 104°(0°C ~ 40°C)

Monitor Dimensions:

