

TECHNICAL SPECIFICATIONS

L12VDC1A 1 Amp 12 Volt DC Power Supply



L12VDC2A 2 Amp 12 Volt DC Power Supply



FEATURES

- ◆ 1 Amp Output
- ◆ UL/CUL Listed
- ◆ Regulated Power Supply

FEATURES

- ◆ 2 Amp Output
- ◆ UL/CUL Listed
- ◆ Regulated Power Supply

L12VDC1A

L12VDC2A

L12DCCRD10PK


L12DCCON10PKF

L12DCCON10PKM

SPECIFICATION	L12VDC1A	L12VDC2A
Input	AC 100-240V 50/60HZ 0.3A Max	AC 100-240V 50/60HZ 0.5A Max
Output	12 Volts DC, 1Amp (Regulated)	12 Volts DC, 2Amp (Regulated)
Polarity	Center Pin Positive	
Dimensions	26mm x 73mm x 45mm (62 w/plug)	32mm x 73mm x 62mm (78 w/plug)
Net Weight	.2lb / .09kg	.25lb / .11kg
Weatherproof	Indoor Only	
Certifications	UL/CUL, LVL VI	
Country of Origin	Made in China	

12 Volt DC Power Connectors

L12DCCRD10PK 12VDC Male Bare Lead Adapter

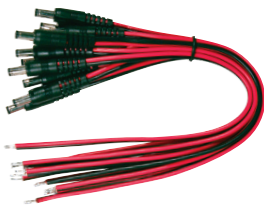

L12DCCON10PKF 12VDC Female Bare Lead Connector



L12DCCON10PKM 12VDC Male Bare Lead Connector



SPECIFICATION	L12DCCRD10PK	L12DCCON10PKF	L12DCCON10PKM
Description	12VDC Male with 12" Bare Lead Cord	12VDC Female with Screw Terminal	12VDC Male with Screw Terminal
Polarity	Center Pin Positive		
Packaging	10-Pack		
Dimensions	φ10x305(mm)	35x12x15(mm)	36x12x12(mm)
Net Weight	.29lb / .13kg	.15lb / .07kg	.1b / .05kg
Country of Origin	Made in China		